
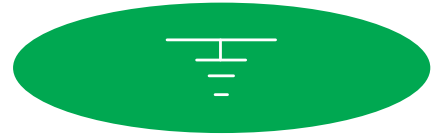


# Ground Terminal Blocks

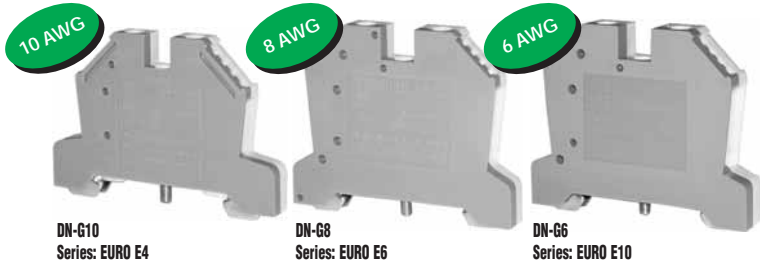





Ground terminal blocks are used to mechanically and electrically connect wires to the DIN rail by means of a conducting clamping foot. In this way, the DIN rail can function as a ground bus bar.

**Note:** The use of an end bracket is not required when a ground block is positioned at the end of a terminal block assembly.

Ground blocks are molded in green and yellow per international standards.



	Part #	Pcs/Pkg	Price/Pkg	Part #	Pcs/Pkg	Price/Pkg	Part#	Pcs/Pkg	Price/Pkg
<b>Ground Block</b>	DN-G10	50	<-->	DN-G8	50	<-->	DN-G6	50	<-->
<b>Ground Terminal Blocks Specifications</b>									
<b>UL Approval*</b>	-	-	24-10AWG	-	-	22-8AWG	-	-	20-6AWG
<b>CSA Approval</b>	-	-	18-12AWG	-	-	18-8AWG	-	-	18-6AWG
<b>VDE Approval</b>	-	-	4mm <sup>2</sup>	-	-	6mm <sup>2</sup>	-	-	10mm <sup>2</sup>
<b>CE Conformity</b>	CE 23/20, CE 23/21			CE 23/20, CE 23/21			CE 23/20, CE 23/21		
<b>Agency File#</b>	E179129, LR84816			E179129, LR84816			E179129, LR84816		
<b>Wire Strip Length</b>	0.39" (10mm)			0.47" (12mm)			0.51" (13mm)		
<b>Tightening Torque</b>	5.5 lb-in. (0.6Nm)			10.6 lb-in. (1.2 Nm)			18 lb-in. (2.0 Nm)		
<b>Density</b>	43 pcs./ft. (142/m)			38 pcs./ft. (125/m)			30 pcs./ft. (100/m)		
<b>Air Temp./Relative</b>	Ambient air temperature: -25°C to -40°C (-13°F to -104°F) Relative humidity: 50% max. at 40°C (104°F), 90% max. at 20°C (-13°F)								

\*Note: For copper wire only

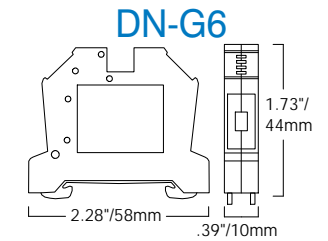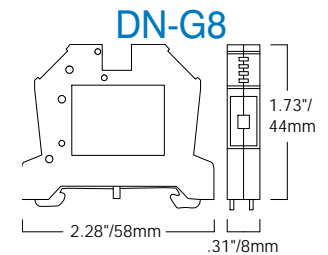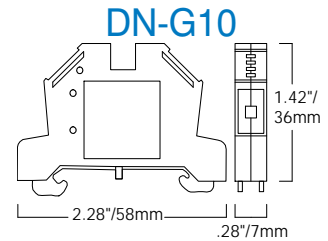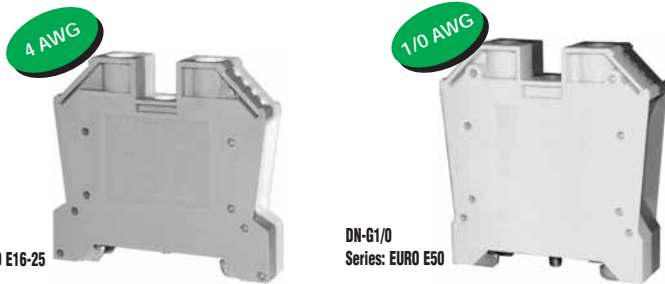

	Part #	Pcs/Pkg	Price/Pkg	Part #	Pcs/Pkg	Price/Pkg
<b>Ground Block</b>	DN-G4	25	<-->	DN-G1/0	25	<-->
<b>Ground Terminal Blocks Specifications</b>						
<b>UL Approval</b>	-	-	14-4AWG	-	-	14-1/0AWG
<b>CSA Approval</b>	-	-	14-4AWG	-	-	14-1/0AWG
<b>VDE Approval</b>	-	-	25mm <sup>2</sup>	-	-	35mm <sup>2</sup>
<b>CE Conformity</b>	CE 23/20, CE 23/21			CE 23/20, CE 23/21		
<b>Agency File#</b>	E179129, LR84816			E179129, LR84816		
<b>Wire Strip Length</b>	0.55" (14mm)			0.71" (18mm)		
<b>Tightening Torque</b>	25.6 lb-in. (3.0 Nm)			44 lb-in. (5.0 Nm)		
<b>Density</b>	25 pcs./ft. (83/m)			19 pcs./ft. (62/m)		

<b>Ground Block Accessories</b>			
	Part#	Pcs/Pkg	Price/Pkg
<b>DIN Rail</b>	35mm DIN rail	10	various
<b>Marking Tags</b>	DN-LT series	100	<-->
<b>Angled Support Bracket</b>	DN-ASB1	50	<-->

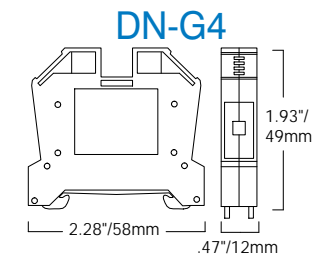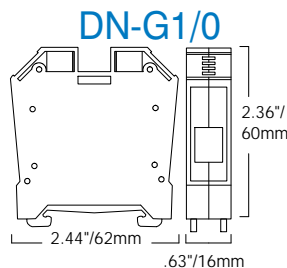

For more information on accessories, see pages 26-20 through 26-22.